



Energy Saver T2

EL/mCan T2 9W

The Philips EnergySaver T2 provides energy efficient lighting in a smaller, sleeker, size that fits more fixtures. The energy saving T2 is a direct replacement for most incandescents, provides soft white light and lasts 11 years* reducing the hassle of frequent replacements.

Product data

• General Characteristics

Base	Candelabra [Candelabra Screw]
Rated Lifetime (hours)	8000 hr

• Light Technical Characteristics

Color Code	827 [CCT of 2700K]
Color Rendering Index	80 (min) Ra8
Color Designation	Warm White
Color Temperature	2700 K
Chromaticity Coordinate X	463 -
Chromaticity Coordinate Y	420 -
Luminous Efficacy Lamp	45 Lm/W
Lumen Maintenance 2000h	80 %
Lumen Maintenance 5000h	70 %
Rated Luminous Flux	410 Lm

• Electrical Characteristics

Watts	9 W
Power Factor	0.55 -
Voltage	110-127 V
Lamp Current mA	150 mA
Line Frequency	50/60 Hz
Dimmable	No

Starting Time	0.2 s
Warm-up Time to 60% Light Outp	180 (max) s

• Environmental Characteristics

Energy Efficiency Label (EEL)	A
-------------------------------	---

• Measuring Conditions

Switching cycle	5000X
-----------------	-------


• Product Dimensions

Overall Length C	115.5 (max) mm
Diameter D	41.5 (max) mm
Width F	39 (max) mm

• Product Data


Product number	417410
Full product name	EL/mCan T2 9W
Short product name	EL/mCan T2 9W 6/1
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677417413
Bar code on case	50046677417418
Logistics code(s)	929689982903
eop_net_weight_pp	0.001 kg

Dimensional drawing

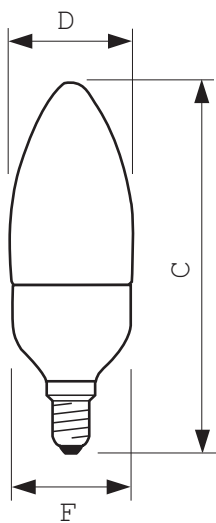

E12/E14, B35/B39/EL/A MCAN

Product	C (Max)	D (Max)	F (Max)
Candle 9W/827 E12 110-127V 50/60Hz	115.5	41.5	39

 

E12



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change