



Frost / Clear

75W Med 120-130V A21 FR 2WR

The Philips Family of Standard Frost and Clear bulbs are good for everyday use. Clear bulbs provide sparkle, especially in fixtures that are made of chrome, have mirrored surfaces, multiple sockets or have cut glass parts. If glare is a problem, use a dimmer or a lower wattage bulb to reduce brightness. Clear bulbs are also used in fixtures with reflectors. Frost bulbs provide soft light with reduced glare.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Bulb	A21
Bulb Finish	Frosted
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Gas
Rated Avg. Life @ 120v	2854 hr

• Light Technical Characteristics

Initial lumen	1110 Lm
Initial Lumens @ 120V	858 Lm

• Electrical Characteristics

Watts	75 W
Voltage	120-130 V

• Product Dimensions

Max Overall Length (MOL) - C	5.312 (max) in
------------------------------	----------------

Diameter D 2.625 in

• Footnotes


Footnotes Incandescent 909 [Pursuant to California law, these incandescent lamps CANNOT be used or offered for sale in the state of California.(909)]

• Product Data

Product number	313056
Full product name	75W Med 120-130V A21 FR 2WR
Short product name	75W Med 120-130V A21 FR 2WR
Pieces per Sku	1
eop_pck_cfg	120
Skus/Case	120
Bar code on pack	46677313050
Bar code on case	50046677313055
Logistics code(s)	920033934302
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

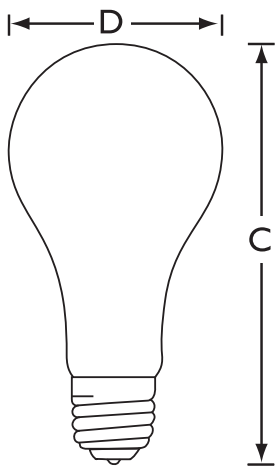

A21



E26

E26, A21

Product	C (Max)	D (Norm)
75W E26 120-130V A21 FR	5.312	2.625



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change