



Frost / Clear

150W 120-130V A23 CL 2WR

The Philips Family of Standard Frost and Clear bulbs are good for everyday use. Clear bulbs provide sparkle, especially in fixtures that are made of chrome, have mirrored surfaces, multiple sockets or have cut glass parts. If glare is a problem, use a dimmer or a lower wattage bulb to reduce brightness. Clear bulbs are also used in fixtures with reflectors. Frost bulbs provide soft light with reduced glare.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A23
Bulb Finish	Clear
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Gas
RatedAvgLife(See Family Notes)	750 hr
Rated Avg. Life @ 120v	1275 hr
Estimated Energy Cost/YR	19.51 \$
Life with 3h/day use [years]	0.3 an

• Light Technical Characteristics

Color Temperature	2870 K
Initial lumen	2945 Lm
Initial Lumens @ 120V	2255 Lm

• Electrical Characteristics

Watts	150 W
Voltage	120-130 V

• Product Dimensions

Light Center Length L	4.625 in
Max Overall Length (MOL) - C	6.313 (max) in
Diameter D	2.625 in

• Product Data


Product number	374199
Full product name	150W 120-130V A23 CL 2WR
Short product name	150W 120-130V A23 CL 2WR
Pieces per Sku	1
eop_pck_cfg	60
Skus/Case	60
Bar code on pack	46677374198
Bar code on case	50046677374193
Logistics code(s)	920065834302
eop_net_weight_pp	0.001 kg

Dimensional drawing

PHILIPS

sense and simplicity

Dimensional drawing

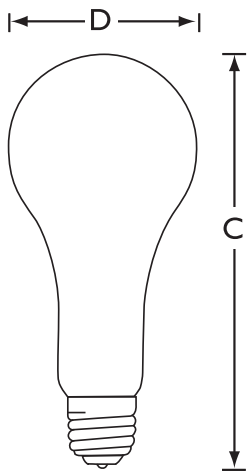

A23



E26

E26, A23

Product	C (Max)	D (Norm)
150W E26 120-130V A23 CL	6.313	2.625



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change