



# Frost / Clear

200W Med 120-130V A23 CL CDA 2WR

The Philips Family of Standard Frost and Clear bulbs are good for everyday use. Clear bulbs provide sparkle, especially in fixtures that are made of chrome, have mirrored surfaces, multiple sockets or have cut glass parts. If glare is a problem, use a dimmer or a lower wattage bulb to reduce brightness. Clear bulbs are also used in fixtures with reflectors. Frost bulbs provide soft light with reduced glare.

## Product data

### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A23
Bulb Finish	Clear
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Gas
RatedAvgLife(See Family Notes)	750 hr
Rated Avg. Life @ 120v	1250 hr

### • Light Technical Characteristics

Initial lumen	3600 Lm
Initial Lumens @ 120V	3310 Lm

### • Electrical Characteristics

Watts	200 W
-------	-------

Voltage	120-130 V
---------	-----------

### • Product Dimensions


Light Center Length L	4.625 in
Max Overall Length (MOL) - C	6.313 (max) in
Diameter D	2.625 in

### • Product Data

Product number	374272
Full product name	200W Med 120-130V A23 CL CDA 2WR
Short product name	200W Med 120-130V A23 CL CDA 2WR
Pieces per Sku	1
eop_pck_cfg	60
Skus/Case	60
Bar code on pack	46677374273
Bar code on case	50046677374278
Logistics code(s)	920080734302
eop_net_weight_pp	0.001 kg

## Dimensional drawing

Dimensional drawing

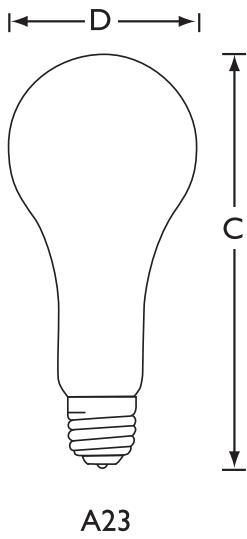

E26

E26, A23

Product	C (Max)	D (Norm)
200W E26 120-130V A23 CL	6.313	2.625



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, July 31  
data subject to change