

Standard Life PS

Std 300W Med 120-130V PS25 CL 1WR



Standard Life Incandescent, vacuum or gas-filled lamp has a crystal clear bulb and a completely visible filament, so the brightness of the light is not 'softened.' It imparts a sparkling radiance to larger luminaires and wall brackets with textured or satin-etched glass and cut crystal. It is the appropriate lamp for large luminaires with clear glass bowls, mounted indoors or outdoors. It is recommended in all such cases where brilliance and sparkle are more important than the avoidance of glare. These lamps are also used for indirect lighting in closed luminaires.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	PS25
Bulb Finish	Clear
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	6280 Lm
---------------	---------

• Electrical Characteristics

Watts	300 W
Voltage	120-130 V

• Product Dimensions

Max Overall Length (MOL) - C	6.938 (max) in
------------------------------	----------------


• Product Data

Product number	133918
Full product name	Std 300W Med 120-130V PS25 CL 1WR
Short product name	Std 300W Med 120-130V PS25 CL 1WR
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677133917
Bar code on case	50046677133912
Logistics code(s)	920140734302
eop_net_weight_pp	0.001 kg


PHILIPS

sense and simplicity

Dimensional drawing

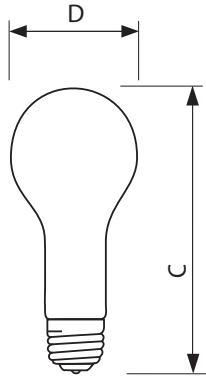

E26, PS25

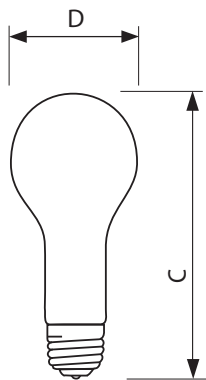

E26, PS25



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change