



Standard Life PS

Std 300W 120V PS25 FR 1WR

Standard Life Incandescent, vacuum or gas-filled lamp has a crystal clear bulb and a completely visible filament, so the brightness of the light is not 'softened.' It imparts a sparkling radiance to larger luminaires and wall brackets with textured or satin-etched glass and cut crystal. It is the appropriate lamp for large luminaires with clear glass bowls, mounted indoors or outdoors. It is recommended in all such cases where brilliance and sparkle are more important than the avoidance of glare. These lamps are also used for indirect lighting in closed luminaires.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	PS25
Bulb Finish	Frosted
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	Household
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	6100 Lm
---------------	---------

• Electrical Characteristics

Watts	300 W
Voltage	120 V

• Product Dimensions

Max Overall Length (MOL) - C	6.938 (max) in
------------------------------	----------------


• Product Data

Product number	389411
Full product name	Std 300W 120V PS25 FR 1WR
Short product name	Std 300W 120V PS25 FR 1WR
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677101237
Bar code on case	50046677389418
Logistics code(s)	920140836307
eop_net_weight_pp	0.001 kg


PHILIPS

sense and simplicity

Dimensional drawing

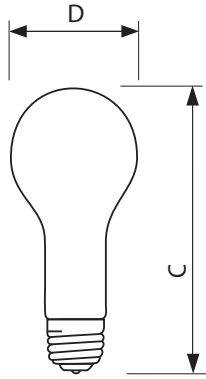

E26, PS25

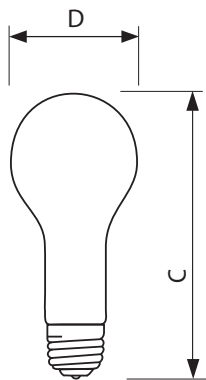

E26, PS25



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change