



Extended Service

Ext Ser 300W Med 130V PS25 FR 2WR

Philips Econ-o-watt® Extended Service Lamps can directly replace standard life incandescent lamps, offering instant energy savings for many applications.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	PS25
Bulb Finish	Frosted
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	Extended Service
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	5060 Lm
---------------	---------

• Electrical Characteristics

Watts	300 W
Voltage	130 V

• Product Dimensions

Max Overall Length (MOL) - C	6.938 (max) in
------------------------------	----------------


• Product Data

Product number	350090
Full product name	Ext Ser 300W Med 130V PS25 FR 2WR
Short product name	ExtSer 300W Med 130V PS25 FR 2WR
Pieces per Sku	1
eop_pck_cfg	60
Skus/Case	60
Bar code on pack	46677350093
Bar code on case	50046677350098
Logistics code(s)	920146336102
eop_net_weight_pp	0.001 kg


PHILIPS

sense and simplicity

Dimensional drawing

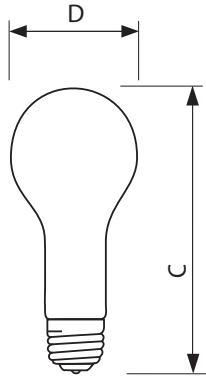

E26, PS25

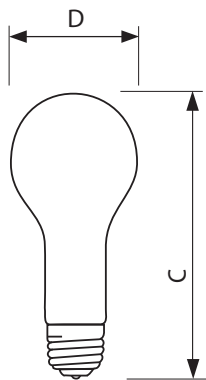

E26, PS25



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change