



Marine / RV

Marine/RV 50W Med 12V A19 FR 1CT

Philips Specialty Marine/RV Incandescents offers light in low volt applications. These low volt A shape lamps run on 12Volt electrical systems found in RV and Marine applications.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Frosted
Filament Shape	C-6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Atmosphere	Gas
Estimated Energy Cost/YR	6.02 \$
Life with 3h/day use [years]	0.9 an

• Light Technical Characteristics

Initial lumen	875 Lm
---------------	--------

• Electrical Characteristics

Watts	50 W
Voltage	12 V

• Product Dimensions


Light Center Length L	2.874 in
Max Overall Length (MOL) - C	4.250 (max) in
Diameter D	2.375 in

• Product Data

Product number	167080
Full product name	Marine/RV 50W Med 12V A19 FR 1CT
Short product name	Mar/RV 50W Med 12V A19 FR 1CT
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677167080
Bar code on case	50046677167085
Logistics code(s)	920585417104
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

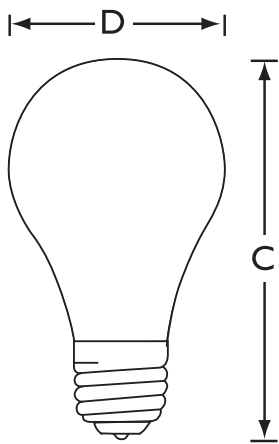

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 50W E26 12V A19 FR	4.250	2.375



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change