



Soft White Three Way

30-70-100W 3 C Med 120V A21 SW 1SL

Philips Family of Incandescents provide the perfect light for general lighting in a variety of applications. The Soft White 3-way provides 3 levels of light for the ultimate in soft, uniform, diffused illumination with reduced glare.

Product data

• General Characteristics

Base	3 Contact Medium [3 Contact Medium Screw]
Base Information	Brass [Brass Base]
Bulb	A21
Bulb Finish	Soft White
Filament Shape	2CC-8 [Axial]
Operating Position	Base Down [Standing or Base Down (BD)]
Main Application	General Lighting

• Electrical Characteristics

Watts	30-100 W [30-70-100]
Voltage	120 V

• Product Dimensions

Max Overall Length (MOL) - C	5.313 (max) in
------------------------------	----------------


Diameter D 2.625 in

• Product Data

Product number	366625
Full product name	30-70-100W 3 C Med 120V A21 SW 1SL
Short product name	30-70-100W 3 C Med 120V A21 SW 1SL
Pieces per Sku	1
Skus/Case	12
Bar code on pack	046677101183
Bar code on case	50046677101188
Logistics code(s)	920588036301

Dimensional drawing

Dimensional drawing

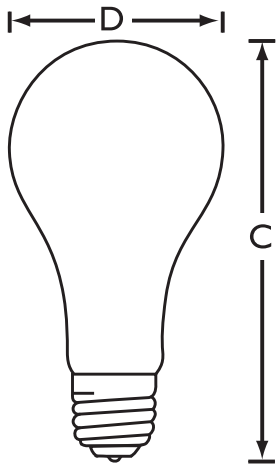

A21

E26d, A21

Product	C (Max)	D (Norm)
30-70-100W E26d 120V A21 SW	5.313	2.625



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change