



Extended Service

Ext Ser 60W 130V A19 FR 2WR

Philips Econ-o-watt® Extended Service Lamps can directly replace standard life incandescent lamps, offering instant energy savings for many applications.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Frosted
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Extended Service
Atmosphere	Gas
Rated Avg. Life @ 120v	5000 hr
Estimated Energy Cost/YR	7.23 \$
Life with 3h/day use [years]	2.3 an

• Light Technical Characteristics

Color Temperature	2670 K
Initial lumen	720 Lm
Initial Lumens @ 120V	540 Lm

• Electrical Characteristics

Watts	60 W
Voltage	130 V

• Product Dimensions

Light Center Length L	2.953 in
Max Overall Length (MOL) - C	4.438 (max) in
Diameter D	2.375 in

• Footnotes


Footnotes Incandescent	905 [Consider the compact fluorescent lamps for energy savings.]
Footnotes Incandescent	909 [Pursuant to California law, these incandescent lamps CANNOT be used or offered in the state of California. (909)]

• Product Data

Product number	222463
Full product name	Ext Ser 60W 130V A19 FR 2WR
Short product name	ExtSer 60W 130V A19 FR 2WR
Pieces per Sku	1
eop_pck_cfg	48
Skus/Case	48
Bar code on pack	46677222468
Bar code on case	50046677222463
Logistics code(s)	920626136102
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

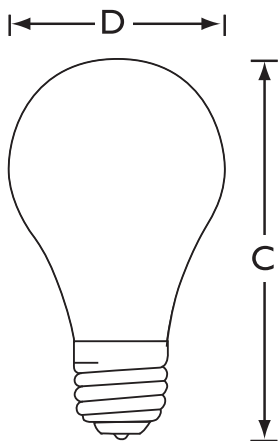

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 60W E26 130V A19 FR	4.438	2.375



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change