

# Soft White



Soft White 75W Med 120V A19 SW 4OW

Philips Family of Incandescents provide the perfect light for general lighting in a variety of applications. The soft White Lamps provide the ultimate in soft, uniform, diffused illumination with reduced glare.

## Product data

### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Soft White
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Gas

### • Light Technical Characteristics

Initial lumen	1180 Lm
---------------	---------

### • Electrical Characteristics

Watts	75 W
Voltage	120 V

### • Product Dimensions

Light Center Length L	2.953 in
--------------------------	----------

Max Overall Length (MOL) - C	4.438 (max) in
Diameter D	2.375 in

### • Footnotes


Footnotes Incandescent	905 [Consider the compact fluorescent lamps for energy savings.]
Footnotes Incandescent	909 [Pursuant to California law, these incandescent lamps CANNOT be used or offered in the state of California. (909)]

### • Product Data

Product number	374850
Full product name	Soft White 75W Med 120V A19 SW 4OW
Short product name	SW 75W Med 120V A19 SW 4OW
Pieces per Sku	4
Skus/Case	12
Bar code on pack	046677104573
Bar code on case	50046677104578
Logistics code(s)	920630236351

## Dimensional drawing

Dimensional drawing

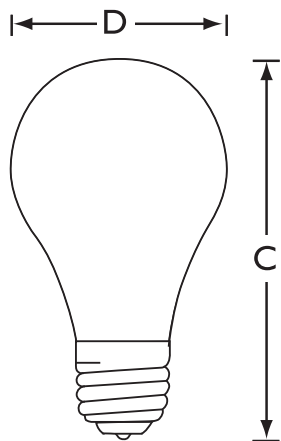

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 75W E26 120V A19 SW	4.438	2.375



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, July 31  
data subject to change