

Soft White

Soft White 100W Med 120V A19 SW 4OW



Philips Family of Incandescents provide the perfect light for general lighting in a variety of applications. The soft White Lamps provide the ultimate in soft, uniform, diffused illumination with reduced glare.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Soft White
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Household
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	1620 Lm
---------------	---------

• Electrical Characteristics

Watts	100 W
Voltage	120 V

• Product Dimensions

Light Center Length L	2.953 in
Max Overall Length (MOL) - C	4.438 (max) in

Diameter D	2.375 in
------------	----------

• Footnotes


Footnotes Incandescent	905 [Consider the compact fluorescent lamps for energy savings.]
Footnotes Incandescent	909 [Pursuant to California law, these incandescent lamps CANNOT be used or offered in the state of California. (909)]

• Product Data

Product number	132548
Full product name	Soft White 100W Med 120V A19 SW 4OW
Short product name	SW 100W Med 120V A19 SW 4OW
Pieces per Sku	4
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677104580
Bar code on case	50046677132540
Logistics code(s)	920640236363
eop_net_weight_pp	0.010 kg

Dimensional drawing

Dimensional drawing

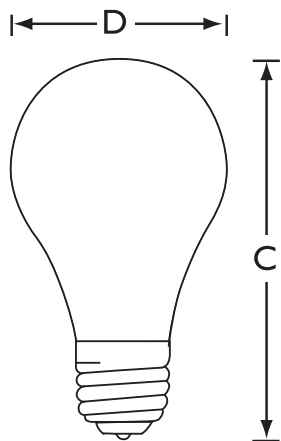

A19



E26

E26, A19

Product	C (Max)	D (Nom)
Std 100W E26 120V A19 SW	4.438	2.375



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, July 31
data subject to change