



Mini-Candelabra

50W Mini-Can 120V T4 CL 1BC

Bright, white light with higher performance for accent lighting Halogen Mini Candelabra T4 Capsule lamps provide bright, white light for decorative and accent lighting and general illumination. Offered in T4 bulb size with mini candelabra base configurations. These lamps offer a rated average life ranging from 1000 to 2000 hours depending upon the product. * Rated average life is the length of operation (in hours) at which point an average of 50% of the lamps will still be operational and 50% will not.

Product data

• General Characteristics

Base	Mini Candelabra [Mini Candelabra]
Bulb	T4
Bulb Finish	Clear
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Atmosphere	Gas
RatedAvgLife(See Family Notes)	1000 hr

• Light Technical Characteristics

Color Rendering Index	100 Ra8
-----------------------	---------

• Electrical Characteristics

Watts	50 W
Voltage	120 V

• Product Dimensions

Light Center Length L	1.38 in
Max Overall Length (MOL) - C	2.75 (max) in


• Product Data

Product number	203471
Full product name	50W Mini-Can 120V T4 CL 1BC
Short product name	BC50Q/CL 120V 12/1PK
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677203474
Bar code on case	50046677203479
Logistics code(s)	924711136382
eop_net_weight_pp	0.009 kg


PHILIPS

sense and simplicity

Dimensional drawing

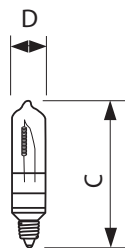

E11, T4

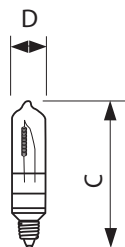

E11, T4



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change