

# PAR20

## 50W Med 120V PAR20 SP 10D CL



Philips Halogen PAR lamps will provide bright, white light across the product line and feature excellent beam qualities for accent or ambient lighting. Their optimized coil and burner design allows for clear, crisp lighting effects with excellent color rendering, making it easy to optimize the look and feel of your store and your merchandise.

### Product data

#### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Brass [Brass Base]
Bulb	PAR20 [PAR 2.5 inch]
Bulb Material	Hard Glass
Bulb Finish	Clear
Reflector Finish	Aluminized
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	Indoor Reflector
Atmosphere	Gas
RatedAvgLife(See Family Notes)	3000 hr

#### • Light Technical Characteristics

Beam Description	Spot
Beam Angle	10 D
Approx. MBCP	4000 cd
Color Rendering Index	100 Ra8
Color Temperature	2900 K
Initial lumen	530 Lm

#### • Electrical Characteristics

Watts	50 W
Voltage	120 V


#### • Product Dimensions

Max Overall Length (MOL) - C	3.375 (max) in
Diameter D	2.5 in


#### • Product Data

Product number	229062
Full product name	50W Med 120V PAR20 SP 10D CL
Short product name	50W Med 120V PAR20 SP 10D CL
Pieces per Sku	1
eop_pck_cfg	15
Skus/Case	15
Bar code on pack	46677229061
Bar code on case	50046677229066
Logistics code(s)	924757101805
eop_net_weight_pp	0.120 kg

Dimensional drawing

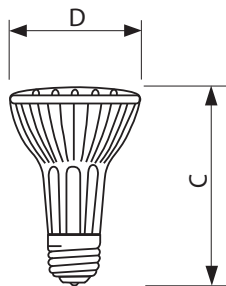

E26, PAR20, Narrow Spot

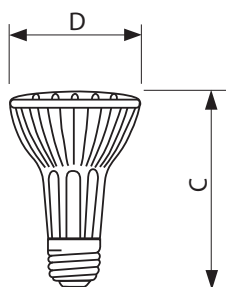

E26, PAR20, Narrow Spot



E26



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change