

PAR38 Medium Side Prong

90W Med Side Prg 130V PAR38 FL 25D CL



Philips Halogen PAR lamps make it easy to optimize the look and feel of your store, your merchandise, and will provide a comfortable shopping experience, at lower operating costs.

Product data

• General Characteristics

Base	Med. Side Prong [Medium Side Prong (PAR Lamps)]
Base Information	Aluminum [Aluminum Base]
Bulb	PAR38 [PAR 4.75 inch/121mm]
Bulb Material	Hard Glass
Bulb Finish	Clear
Reflector Finish	Aluminized
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	Outdoor
Atmosphere	Gas
RatedAvgLife(See Family Notes)	5000 hr
Estimated Energy Cost/YR	9.24 \$

• Light Technical Characteristics

Beam Description	Flood [Flood]
Beam Angle	25 D
Approx. MBCP	4500 cd
Color Rendering Index	100 Ra8
Color Temperature	2910 K

Initial lumen 1340 Lm

• Electrical Characteristics

Watts 77 W
Voltage 130 V

• Product Dimensions


Max Overall Length (MOL) - C 4.043 (max) in
Diameter D 4.75 in

• Product Data


Product number 388900
Full product name 90W Med Side Prg 130V PAR38 FL 25D CL
Short product name 90W Med Side Prg 130V PAR38 FL 25D CL
Pieces per Sku 1
Skus/Case 12
Bar code on pack 046677388904
Bar code on case 50046677388909
Logistics code(s) 924757119040

PAR38 Medium Side Prong

Dimensional drawing

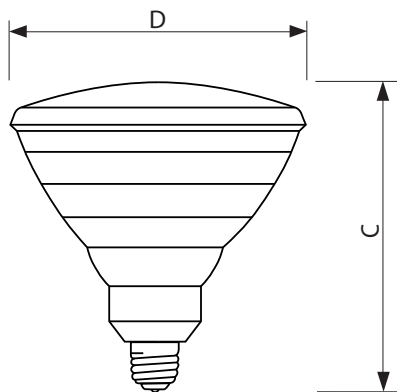

E26, PAR38

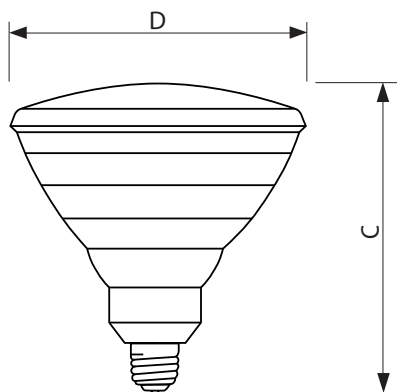

E26, PAR38



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change