



# Mini-Candelabra

150W Mini-Can 130V T4 CL 1CT

Bright, white light with higher performance for accent lighting Halogen Mini Candelabra T4 Capsule lamps provide bright,white light for decorative and accent lighting and general illumination. Offered in T4 bulb size with mini candelabra base configurations. These lamps offer a rated average life ranging from 1000 to 2000 hours depending upon the product. \* Rated average life is the length of operation (in hours) at which point an average of 50% of the lamps will still be operational and 50% will not.

## Product data

### • General Characteristics

Base	Mini Candelabra [Mini Candelabra]
Bulb	T4
Bulb Finish	Clear
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Atmosphere	Gas
RatedAvgLife(See Family Notes)	1000 hr

### • Light Technical Characteristics

Color Rendering Index	100 Ra8
Color Temperature	2800 K
Initial lumen	2800 Lm

### • Electrical Characteristics

Watts	150 W
-------	-------

Voltage	130 V
---------	-------

### • Product Dimensions

Light Center Length L	1.38 in
Max Overall Length (MOL) - C	3 (max) in


### • Product Data

Product number	200493
Full product name	150W Mini-Can 130V T4 CL 1CT
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677115111
Bar code on case	50046677115116
Logistics code(s)	924790436381
eop_net_weight_pp	0.009 kg


# PHILIPS

sense and simplicity

## Dimensional drawing

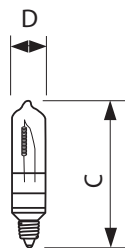

E11, T4

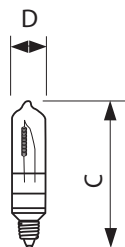

E11, T4



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change