



Reflector Flood

Reflector 45W Med 130V R20 FL 1CT

Philips Family of Specialty Incandescents provide the perfect light for dramatic accents and display lighting as well as general lighting in a variety of applications. These flood lamps produce homogeneous beams of high intensity for general illumination.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	R-20
Bulb Finish	Frosted
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Indoor Reflector
Atmosphere	Gas

• Light Technical Characteristics

Beam Description	Flood [Flood]
Initial lumen	380 Lm

• Electrical Characteristics

Watts	45 W
Voltage	130 V

• Product Dimensions

Max Overall Length (MOL) - C	3.94 (max) in
------------------------------	---------------

• Product Data

Product number	203224
Full product name	Reflector 45W Med 130V R20 FL 1CT
Short product name	Refl 45W Med 130V R20 FL 1CT
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677203221
Bar code on case	50046677203226
Logistics code(s)	925154436103
eop_net_weight_pp	0.001 kg

Dimensional drawing


PHILIPS

sense and simplicity

Dimensional drawing

E26, R20

Product	C (Max)	D (Norm)
45W E26 130V R20	3.94	-

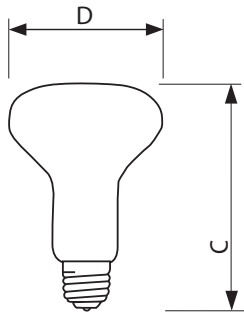

E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change