

DuraMax Clear

DuraMax 150W Med 120V A21 CL 1SL



Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Bulb	A21
Bulb Finish	Clear
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	Household
Atmosphere	Gas
Estimated Energy Cost/YR	18.07 \$
Life with 3h/day use [years]	1.4 an

• Light Technical Characteristics

Color Temperature	2780 K
Initial lumen	2120 Lm

• Electrical Characteristics

Watts	150 W
Voltage	120 V

• Product Dimensions

Max Overall Length (MOL) - C	5.312 (max) in
------------------------------	----------------

Diameter D 2.625 in

• Footnotes


Footnotes Incandescent 909 [Pursuant to California law, these incandescent lamps CANNOT be used or offered for sale in the state of California.(909)]

• Product Data

Product number	150094
Full product name	DuraMax 150W Med 120V A21 CL 1SL
Short product name	DuraMax 150W Med 120V A21 CL 1SL
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677167998
Bar code on case	50046677150094
Logistics code(s)	925157236302
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

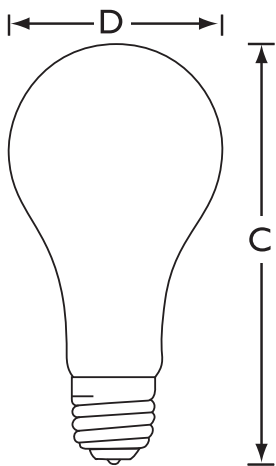

A21



E26

E26, A21

Product	C (Max)	D (Norm)
150W E26 120V A21 CL	5.312	2.625



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change