



# DuraMax Three Way

DuraMax 50-250W 3 C Med 120V A21 SW 1SL

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs

## Product data

### • General Characteristics

Base	3 Contact Medium [3 Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A21
Bulb Finish	Soft White
Filament Shape	2CC-8 [Axial]
Operating Position	Base Down [Standing or Base Down (BD)]
Main Application	General Lighting
Atmosphere	Gas
Estimated Energy Cost/YR	6.02 \$
Life with 3h/day use [years]	1.6 an

### • Light Technical Characteristics

Color Temperature	2720 K
-------------------	--------

### • Electrical Characteristics

Watts	50-250 W [50-200-250]
-------	-----------------------

Voltage	120 V
---------	-------

### • Product Dimensions


Max Overall Length (MOL) - C	5.9375 (max) in
Diameter D	2.625 in

### • Product Data

Product number	169490
Full product name	DuraMax 50-250W 3 C Med 120V A21 SW 1SL
Short product name	DuraMax 50-250W 3 C Med 120V A21 SW 1SL
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677169497
Bar code on case	50046677169492
Logistics code(s)	925158736301
eop_net_weight_pp	0.001 kg

## Dimensional drawing

## Dimensional drawing

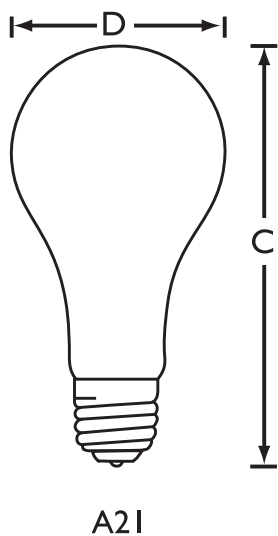

### E26d, A21

Product	C (Max)	D (Norm)
50-200-250W E26d 120V A21 SW	5.9375	2.625



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change