



DuraMax Deco Globe

DuraMax Deco 25W 120V G16 1/2 WH/LL 2BC

Philips DuraMax® Long Life Deco Globe Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. DuraMax Deco globe bulbs are available in a wide assortment of shapes, sizes and wattages. Clear globes add decorative sparkle, white globes emit soft white light and half-chrome provides decorative sparkle and reduced glare.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	G16 1/2
Bulb Finish	White
Filament Shape	C-7A [Ring]
Operating Position	Base Down +/- 90D [Standing +/-90D or Base Down (BDH)]
Main Application	Decorative
Atmosphere	Vacuum [Vacuum]

• Light Technical Characteristics

Initial lumen	165 Lm
---------------	--------

• Electrical Characteristics

Watts	25 W
Voltage	120 V

• Product Dimensions

Max Overall Length (MOL) - C	3 (max) in
Diameter D	2.0625 in


• Product Data

Product number	168476
Full product name	DuraMax Deco 25W 120V G16 1/2 WH/LL 2BC
Short product name	DuraMx Deco 25W 120V G16 1/2 WH/LL 2BC
Pieces per Sku	2
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677168476
Bar code on case	50046677168471
Logistics code(s)	925164236303
eop_net_weight_pp	0.000 gr

PHILIPS

sense and simplicity


Dimensional drawing

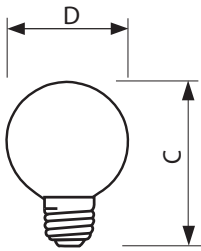

E26, G16 1/2



E26

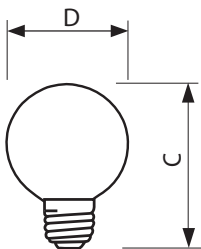

E26, G16 1/2



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change