



# DuraMax Three Way

DuraMax 30-70-100W 120V A21 SW 1SL

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs

## Product data

### • General Characteristics

Base	3 Contact Medium [3 Contact Medium Screw]
Base Information	Brass [Brass Base]
Bulb	A21
Bulb Finish	Soft White
Filament Shape	2CC-8 [Axial]
Operating Position	Base Down +/- 90D [Standing +/- 90D or Base Down (BDH)]
Main Application	General Lighting
Atmosphere	Gas

### • Light Technical Characteristics

Initial lumen	960 Lm
---------------	--------

### • Electrical Characteristics

Watts	30-100 W [30-70-100]
Voltage	120 V

### • Product Dimensions


Max Overall Length (MOL) - C	5.313 (max) in
Diameter D	2.625 in

### • Product Data

Product number	169474
Full product name	DuraMax 30-70-100W 120V A21 SW 1SL
Short product name	DuraMax 30-70-100W 120V A21 SW 1SL
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677169473
Bar code on case	50046677169478
Logistics code(s)	925176336309
eop_net_weight_pp	0.001 kg

## Dimensional drawing

## Dimensional drawing

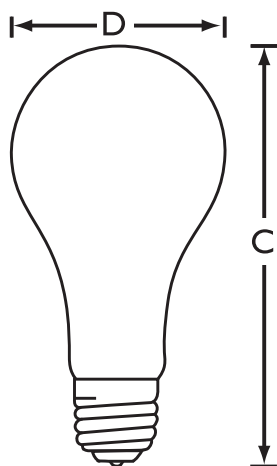

A21

### E26d, A21

Product	C (Max)	D (Norm)
30-70-100W E26d 120V A21 SW	5.313	2.625



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change