



DuraMax Three Way

DuraMax 50-100-150W 120V A-21 WH 1SL

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs

Product data

• General Characteristics

Base	3 Contact Medium [3 Contact Medium Screw]
Base Information	Brass [Brass Base]
Bulb	A21
Bulb Finish	Soft White
Filament Shape	2CC-8 [Axial]
Operating Position	Base Down [Standing or Base Down (BD)]
Main Application	General Lighting
Atmosphere	Gas
Estimated Energy Cost/YR	6.02 \$
Life with 3h/day use [years]	1.6 an

• Light Technical Characteristics

Color Temperature	2720 K
-------------------	--------

• Electrical Characteristics

Watts	50-150 W [50-100-150]
-------	-----------------------

Voltage	120 V
---------	-------

• Product Dimensions


Max Overall Length (MOL) - C	5.313 (max) in
Diameter D	2.625 in

• Product Data

Product number	169482
Full product name	DuraMax 50-100-150W 120V A-21 WH 1SL
Short product name	DuraMax 50-100-150W 120V A-21 WH 1SL
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677169480
Bar code on case	50046677169485
Logistics code(s)	925177036328
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

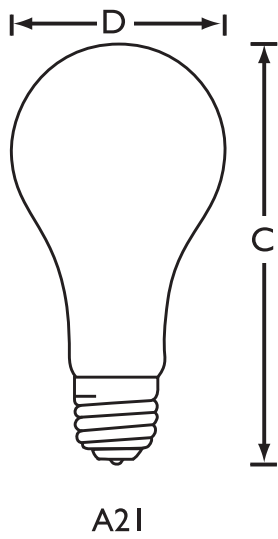

E26d, A21

Product	C (Max)	D (Norm)
50-100-150W E26d 120V A21 SW	5.313	2.625



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change