

DuraMax Soft White



DuraMax 25W Med 120V A19 SW 2OW

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Soft White
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Household
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	235 Lm
---------------	--------

• Electrical Characteristics

Watts	25 W
Voltage	120 V

• Product Dimensions

Light Center Length L	2.953 in
--------------------------	----------

Max Overall Length (MOL) - C	4.438 (max) in
Diameter D	2.375 in

• Product Data


Product number	168682
Full product name	DuraMax 25W Med 120V A19 SW 2OW
Short product name	DuraMax 25W Med 120V A19 SW 2OW
Pieces per Sku	2
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677168681
Bar code on case	50046677168686
Logistics code(s)	925178336313
eop_net_weight_pp	0.000 kg

Dimensional drawing

PHILIPS

sense and simplicity

Dimensional drawing

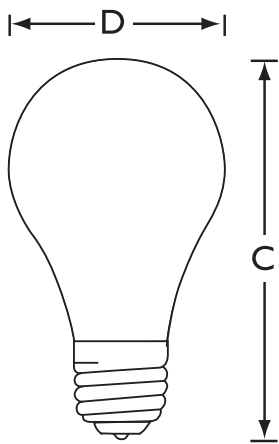

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 25W E26 120V A19 SW	4.438	2.375



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change