



# DuraMax Soft White

DuraMax 200W Med 120V A21 SW longlife

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs.

## Product data

### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Bulb	A21
Bulb Finish	Soft White
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	longlife
Atmosphere	Gas

### • Light Technical Characteristics

Initial lumen	3100 Lm
---------------	---------

### • Electrical Characteristics

Watts	200 W
Voltage	120 V

### • Product Dimensions

Light Center Length L	3.818 in
--------------------------	----------


Max Overall Length (MOL) - C	5.312 (max) in
Diameter D	2.625 in

### • Product Data

Product number	168674
Full product name	DuraMax 200W Med 120V A21 SW longlife
Short product name	DuraMax 200W Med 120V A21 SW longlife
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677168674
Bar code on case	50046677168679
Logistics code(s)	925178436307
eop_net_weight_pp	0.001 kg

## Dimensional drawing

Dimensional drawing

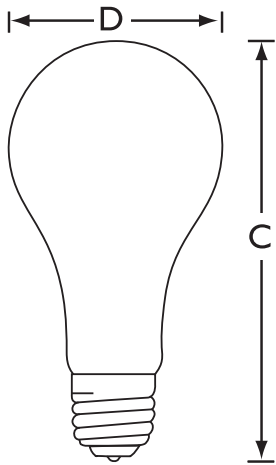

A21



E26

E26, A21

Product	C (Max)	D (Norm)
200W E26 120V A21 SW	5.312	2.625



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change