

DuraMax Deco Globe

DuraMax Deco 40W Med 120V G40 WH 1CT



Philips DuraMax® Long Life Deco Globe Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. DuraMax deco globe bulbs are available in a wide assortment of shapes, sizes and wattages. Clear globes add decorative sparkle, white globes emit soft white light and half-chrome provides decorative sparkle and reduced glare.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	G40
Bulb Finish	White
Filament Shape	C-9 [Pendant]
Operating Position	Universal [Any or Universal (U)]
Main Application	Decorative
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	335 Lm
---------------	--------

• Electrical Characteristics

Watts	40 W
Voltage	120 V

• Product Dimensions

Max Overall Length (MOL) - C	6.938 (max) in
Diameter D	5.028 in


• Product Data

Product number	168583
Full product name	DuraMax Deco 40W Med 120V G40 WH 1CT
Short product name	DuraMax Deco 40W Med 120V G40 WH 1CT
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677168582
Bar code on case	50046677168587
Logistics code(s)	925178636303
eop_net_weight_pp	0.001 kg


PHILIPS

sense and simplicity

Dimensional drawing

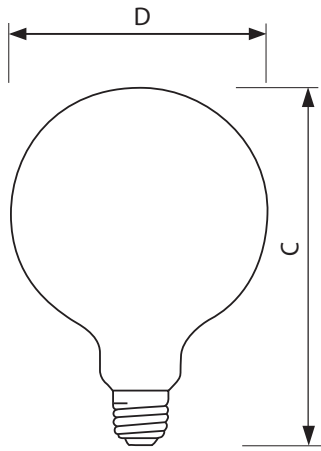

E26, G40

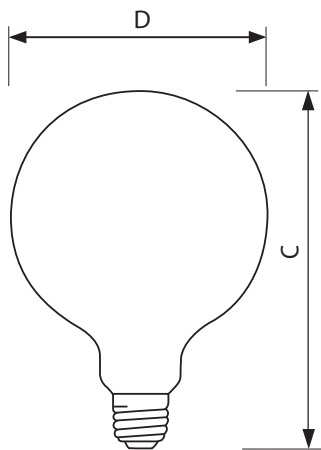

E26, G40



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change