



DuraMax Soft White

DuraMax 150W ES 120V A21 WH 1SL

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Bulb	A21
Bulb Finish	Soft White
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	longlife
Atmosphere	Gas
Estimated Energy Cost/YR	18.07 \$
Life with 3h/day use [years]	1.8 an

• Light Technical Characteristics

Color Temperature	2810 K
Initial lumen	1830 Lm

• Electrical Characteristics

Watts	150 W
Voltage	120 V

• Product Dimensions

Light Center Length L	3.818 in
Max Overall Length (MOL) - C	5.312 (max) in
Diameter D	2.625 in

• Product Data


Product number	168666
Full product name	DuraMax 150W ES 120V A21 WH 1SL
Short product name	DuraMax 150W ES 120V A21 WH 1SL
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677168667
Bar code on case	50046677168662
Logistics code(s)	925179336307
eop_net_weight_pp	0.001 kg

Dimensional drawing

PHILIPS

sense and simplicity

Dimensional drawing

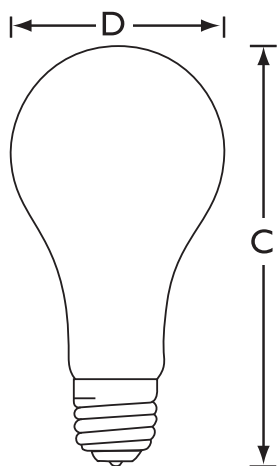

A21



E26

E26, A21

Product	C (Max)	D (Norm)
150W E26 120V A21 SW	5.312	2.625



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change