



DuraMax Fan

DuraMax 60W Med 120V A15 CL/LL 2BC

Philips DuraMax® Long Life Fan Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. Available in clear and white finishes adding a decorative touch to ceiling fan fixtures.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A15
Bulb Finish	Clear
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Fan
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	630 Lm
---------------	--------

• Electrical Characteristics

Watts	60 W
Voltage	120 V

• Product Dimensions

Light Center Length L	2.38 in
--------------------------	---------

Max Overall Length (MOL) - C	3.50 (max) in
Diameter D	1.894 in


• Product Data

Product number	169466
Full product name	DuraMax 60W Med 120V A15 CL/LL 2BC
Short product name	DuraMax 60W Med 120V A15 CL/LL 2BC
Pieces per Sku	2
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677169466
Bar code on case	50046677169461
Logistics code(s)	925181636320
eop_net_weight_pp	0.000 gr


PHILIPS

sense and simplicity

Dimensional drawing

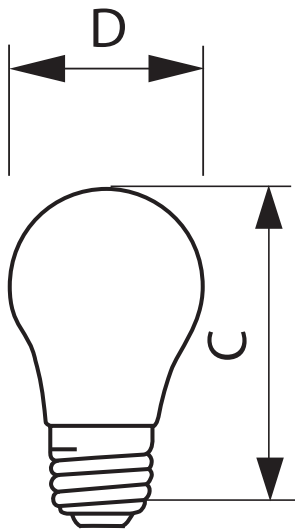

E12/E17/E26, A15

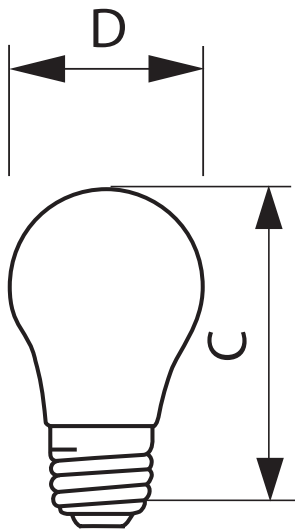

E12/E17/E26, A15



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change