

# DuraMax Deco Globe

DuraMax Deco 25W Med 120V G25 CL/LL 1CT



Philips DuraMax® Long Life Deco Globe Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. DuraMax Deco globe bulbs are available in a wide assortment of shapes, sizes and wattages. Clear globes add decorative sparkle, white globes emit soft white light and half-chrome provides decorative sparkle and reduced glare.

## Product data

### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	G25
Bulb Finish	Clear
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Vanity
Atmosphere	Gas

### • Light Technical Characteristics

Initial lumen	235 Lm
---------------	--------

### • Electrical Characteristics

Watts	25 W
Voltage	120 V

### • Product Dimensions

Light Center Length L	2.874 in
--------------------------	----------

Max Overall Length (MOL) - C	4.438 (max) in
Diameter D	3.125 in


### • Product Data

Product number	168872
Full product name	DuraMax Deco 25W Med 120V G25 CL/LL 1CT
Short product name	DuraMax Deco 25W Med 120V G25 CL/LL 1CT
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677168872
Bar code on case	50046677168877
Logistics code(s)	925186636323
eop_net_weight_pp	0.001 kg


# PHILIPS

sense and simplicity

Dimensional drawing

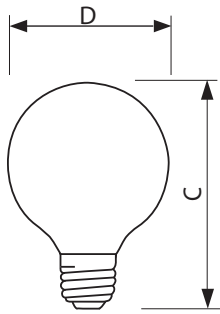

E26, G25

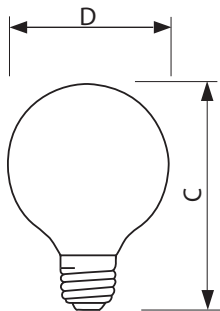

E26, G25



E26



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change