



Deco Globe

DuraMax Deco 25W Med 120V G25 WH/LL 1CT

Decorative globe bulbs add sparkle and are ideal for contemporary décor.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	G25
Bulb Finish	White
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Vanity
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	210 Lm
---------------	--------

• Electrical Characteristics

Watts	25 W
Voltage	120 V

• Product Dimensions

Light Center Length L	2.874 in
--------------------------	----------

Max Overall Length (MOL) - C	4.438 (max) in
Diameter D	3.125 in


• Product Data

Product number	167486
Full product name	DuraMax Deco 25W Med 120V G25 WH/LL 1CT
Short product name	DuraMax Deco 25W Med 120V G25 WH/LL 1CT
Pieces per Sku	1
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677167486
Bar code on case	50046677167481
Logistics code(s)	925186736324
eop_net_weight_pp	0.001 kg


PHILIPS

sense and simplicity

Dimensional drawing

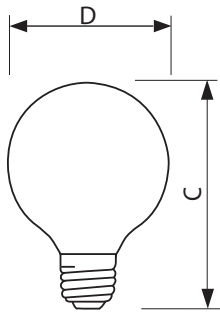

E26, G25

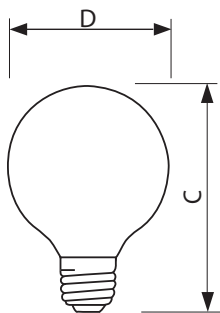

E26, G25



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change