

# DuraMax Deco Bent Tip

DuraMax Deco 40W 120V BA9 1/2 CL/LL 2BC



Philips DuraMax® Long Life Decorative bent tip bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. Philips Duramax decorative bent tip bulbs are available in a variety of wattages with clear and frost finishes. The clear bulbs provide decorative sparkle, while the frost bulbs add a soft glow to add a pleasant touch to home decor.

## Product data

### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	BA9 1/2
Bulb Finish	Clear
Filament Shape	C-7A [Ring]
Operating Position	Base Down +/- 90D [Standing +/-90D or Base Down (BDH)]
Main Application	Decorative
Atmosphere	Gas

### • Light Technical Characteristics

Initial lumen	300 Lm
---------------	--------

### • Electrical Characteristics

Watts	40 W
Voltage	120 V


### • Product Dimensions

Max Overall Length (MOL) - C	4.063 (max) in
Diameter D	1.188 in


### • Product Data

Product number	168203
Full product name	DuraMax Deco 40W 120V BA9 1/2 CL/LL 2BC
Short product name	DuraMax Deco 40W 120V BA9 1/2 CL/LL 2BC
Pieces per Sku	2
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677168209
Bar code on case	50046677168204
Logistics code(s)	925240536308
eop_net_weight_pp	0.000 gr

## Dimensional drawing

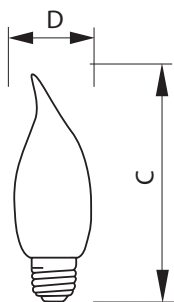

E26, BA9 1/2

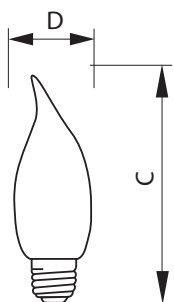

E26, BA9 1/2



E26



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change