



Extended Service

ExtSer 200W 120-130V A23 FR 2WR

Philips Econ-o-watt® Extended Service Lamps can directly replace standard life incandescent lamps, offering instant energy savings for many applications.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A23
Bulb Finish	Frosted
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	Extended Service
Atmosphere	Gas
RatedAvgLife(See Family Notes)	2500 hr
Rated Avg. Life @ 120v	4268 hr

• Light Technical Characteristics

Initial lumen	3250 Lm
Initial Lumens @ 120V	3014 Lm

• Electrical Characteristics

Watts	200 W
-------	-------

Voltage	120-130 V
---------	-----------

• Product Dimensions


Light Center Length L	4.645 in
Max Overall Length (MOL) - C	6.313 (max) in
Diameter D	2.625 in

• Product Data

Product number	281766
Full product name	ExtSer 200W 120-130V A23 FR 2WR
Short product name	ExtSer 200W 120-130V A23 FR 2WR
Pieces per Sku	1
eop_pck_cfg	60
Skus/Case	60
Bar code on pack	46677281762
Bar code on case	50046677281767
Logistics code(s)	925242334302
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

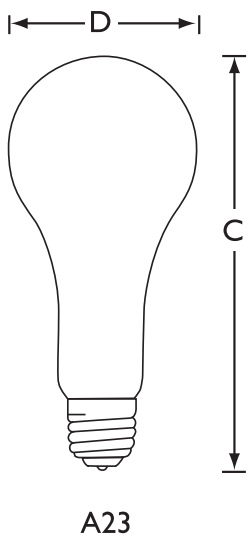

E26, A23

Product	C (Max)	D (Norm)
200W E26 120-130V A23 FR	6.313	2.625



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change