

# DuraMax Deco Bent Tip

DuraMax Deco 60W Cand 120V BA9 CL 2BC



Philips DuraMax® Long Life Decorative bent tip bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. Philips DuraMax decorative bent tip bulbs are available in a variety of wattages with clear and frost finishes. The clear bulbs provide decorative sparkle, while the frost bulbs add a soft glow to add a pleasant touch to home decor.

## Product data

### • General Characteristics

Base	Candelabra [Candelabra Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	BA9
Bulb Finish	Clear
Filament Shape	C-7A [Ring]
Operating Position	Base Down +/- 90D [Standing +/-90D or Base Down (BDH)]
Main Application	Decorative
Atmosphere	Gas

### • Light Technical Characteristics

Initial lumen	550 Lm
---------------	--------

### • Electrical Characteristics

Watts	60 W
Voltage	120 V


### • Product Dimensions

Max Overall Length (MOL) - C	4.188 (max) in
Diameter D	1.125 in


### • Product Data

Product number	168088
Full product name	DuraMax Deco 60W Cand 120V BA9 CL 2BC
Short product name	DuraMax Deco 60W Cand 120V BA9 CL 2BC
Pieces per Sku	2
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677168087
Bar code on case	50046677168082
Logistics code(s)	925251936315
eop_net_weight_pp	0.000 kg


## Dimensional drawing

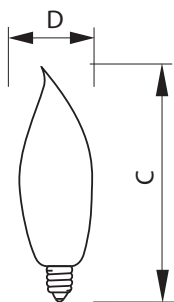

E12, BA9

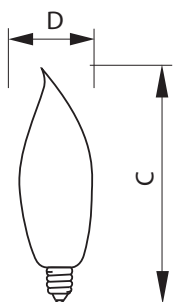

E12, BA9

 

E12



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change