

DuraMax Deco Globe

DuraMax Deco 40W 120V G16 1/2 CL LL 2BC



Philips DuraMax® Long Life Deco Globe Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. DuraMax deco globe bulbs are available in a wide assortment of shapes, sizes and wattages. Clear globes add decorative sparkle, white globes emit soft white light and half-chrome provides decorative sparkle and reduced glare.

Product data

• General Characteristics

Base	Candelabra [Candelabra Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	G16 1/2
Bulb Finish	Clear
Filament Shape	C-7A [Ring]
Operating Position	Base Down +/- 90D [Standing +/-90D or Base Down (BDH)]
Main Application	Decorative
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	300 Lm
---------------	--------

• Electrical Characteristics

Watts	40 W
Voltage	120 V

• Product Dimensions

Max Overall Length (MOL) - C	3 (max) in
Diameter D	2.0625 in


• Product Data

Product number	168468
Full product name	DuraMax Deco 40W 120V G16 1/2 CL LL 2BC
Short product name	DuraMx Deco 40W 120V G16 1/2 CL LL 2BC
Pieces per Sku	2
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677168469
Bar code on case	50046677168464
Logistics code(s)	925261636308
eop_net_weight_pp	0.000 kg


PHILIPS

sense and simplicity


Dimensional drawing

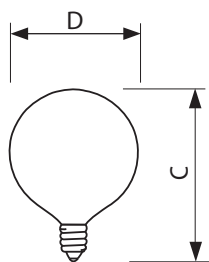

E12, G16 1/2

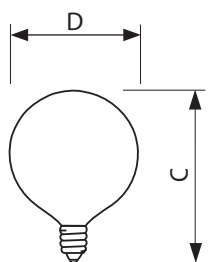

E12, G16 1/2

 

E12



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change