



Rough / Vibration Service

200W Med 120V PS30 FR 1CT

Philips Family of Specialty Incandescents provide the perfect light for dramatic accents and display lighting as well as general lighting in a variety of applications. Rough Service incandescent lamps have an exceptionally strong filament for which a special filament wire is used, which makes these lamps extremely suitable for places where shocks, bumps and vibrations frequently occur. The clear version, with its completely visible filament, is a brilliant light source, whereas the inside-frosted lamp is used wherever well diffused light is required.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	PS30
Bulb Finish	Frosted
Filament Shape	C-9 [Pendant]
Operating Position	Universal [Any or Universal (U)]
Main Application	Industrial Rough Service
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	3500 Lm
---------------	---------

• Electrical Characteristics

Watts	200 W
Voltage	120 V

• Product Dimensions

Max Overall Length (MOL) - C	8.063 (max) in
------------------------------	----------------


• Product Data

Product number	143040
Full product name	200W Med 120V PS30 FR 1CT
Short product name	200W Med 120V PS30 FR 1CT
Pieces per Sku	1
eop_pck_cfg	60
Skus/Case	60
Bar code on pack	46677143046
Bar code on case	50046677143041
Logistics code(s)	925266836102
eop_net_weight_pp	0.001 kg


PHILIPS

sense and simplicity

Dimensional drawing

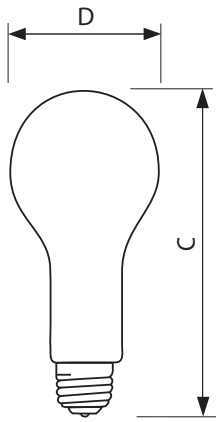

E26, PS30

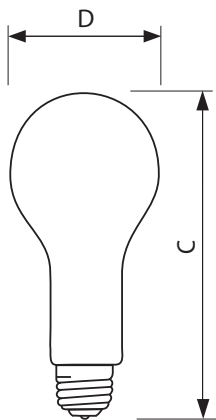

E26, PS30



E26



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change