



# DuraMax Soft White

DuraMax 15W Med 120V A15 SW TP 2OW

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs.

## Product data

### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A15
Bulb Finish	Soft White
Filament Shape	C-9 [Pendant]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Vacuum [Vacuum]

### • Light Technical Characteristics

Initial lumen	115 Lm
---------------	--------

### • Electrical Characteristics

Watts	15 W
Voltage	120 V

### • Product Dimensions

Light Center Length L	2.38 in
--------------------------	---------

Max Overall Length (MOL) - C	3.50 (max) in
Diameter D	1.894 in


### • Product Data

Product number	168609
Full product name	DuraMax 15W Med 120V A15 SW TP 2OW
Short product name	DuraMax 15W Med 120V A15 SW TP 2OW
Pieces per Sku	2
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677168605
Bar code on case	50046677168600
Logistics code(s)	925273136309
eop_net_weight_pp	0.000 gr


# PHILIPS

sense and simplicity

Dimensional drawing

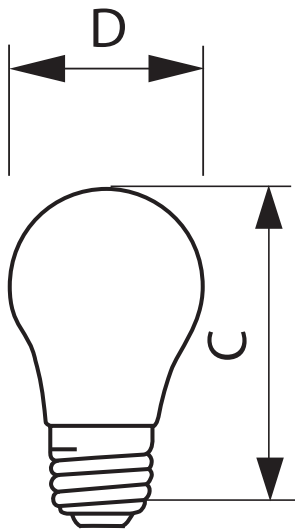

E12/E17/E26, A15

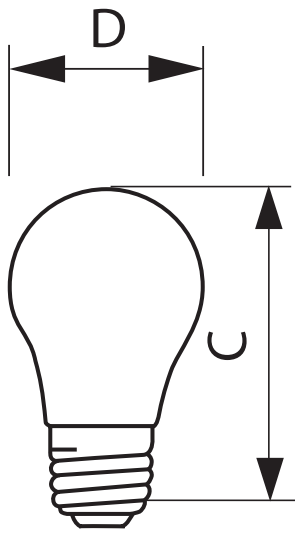

E12/E17/E26, A15



E26



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change