

Appliance

App 40W ES 120V A15 CL 2WR

The Philips Appliance bulb provides the perfect option to light your refrigerator, oven and other household appliances.



Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A15
Bulb Finish	Clear
Filament Shape	C-9 [Pendant]
Operating Position	Universal [Any or Universal (U)]
Main Application	Oven
Atmosphere	Gas
Estimated Energy Cost/YR	4.82 \$
Life with 3h/day use [years]	0.9 an

• Light Technical Characteristics

Color Temperature	2730 K
Initial lumen	445 Lm

• Electrical Characteristics

Watts	40 W
-------	------

Voltage	120 V
---------	-------

• Product Dimensions

Light Center Length L	2.519 in
Max Overall Length (MOL) - C	3.50 (max) in
Diameter D	1.894 in


• Product Data

Product number	200022
Full product name	App 40W ES 120V A15 CL 2WR
Short product name	App 40W ES 120V A15 CL 2WR
Pieces per Sku	1
eop_pck_cfg	120
Skus/Case	120
Bar code on pack	46677200022
Bar code on case	50046677200027
Logistics code(s)	925274336102
eop_net_weight_pp	0.001 kg

PHILIPS

sense and simplicity

Dimensional drawing

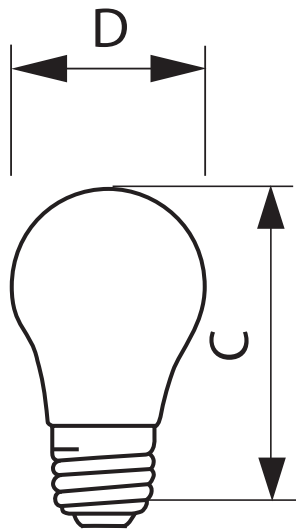

E12/E17/E26, A15



E26



© 2011 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2011, December 21
data subject to change