



## Colors

### 25W Med 120V A19 Transparent Red 1BC

Philips Family of Colored A19 bulbs are ideal for holiday, party or special effects lighting.

#### Product data

##### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Transparent Red
Filament Shape	C-9 [Pendant]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Vacuum [Vacuum]

##### • Electrical Characteristics

Watts	25 W
Voltage	120 V

##### • Product Dimensions

Light Center Length L	2.559 in
--------------------------	----------


Max Overall Length (MOL) - C	3.938 (max) in
Diameter D	2.375 in

##### • Product Data

Product number	144220
Full product name	25W Med 120V A19 Transparent Red 1BC
Short product name	25W Med 120V A19 Transparent Red 1BC
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677144227
Bar code on case	50046677144222
Logistics code(s)	925275736304
eop_net_weight_pp	0.001 kg

#### Dimensional drawing

Dimensional drawing

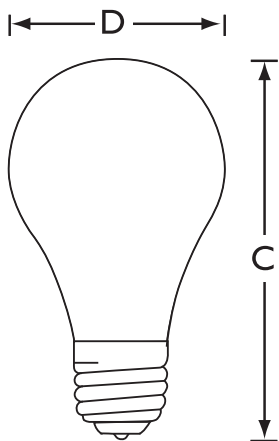

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 25W E26 120V A19 TRPRE	3.938	2.375



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change