



Colors

25W Med 120V A19 Transparent Yellow 1BC

Philips Family of Colored A19 bulbs are ideal for holiday, party or special effects lighting.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Transparent Yellow
Filament Shape	C-9 [Pendant]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Vacuum [Vacuum]

• Electrical Characteristics

Watts	25 W
Voltage	120 V

• Product Dimensions

Light Center Length L	2.559 in
--------------------------	----------


Max Overall Length (MOL) - C	3.938 (max) in
Diameter D	2.375 in

• Product Data

Product number	144238
Full product name	25W Med 120V A19 Transparent Yellow 1BC
Short product name	25W Med 120V A19 Transparent Yellow 1BC
Pieces per Sku	1
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677144234
Bar code on case	50046677144239
Logistics code(s)	925275836304
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

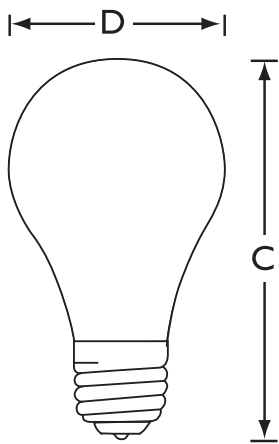

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 25W E26 120V A19 TRPYE	3.938	2.375



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change