



Industrial Service

Ind Ser 60W Med 130V A19 FR 2WR

Philips Econ-o-watt® Industrial Service Lamps can directly replace standard life incandescent lamps, offering instant energy savings for many applications.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Brass [Brass Base]
Bulb	A19
Bulb Finish	Frosted
Filament Shape	C-9 [Pendant]
Operating Position	Universal [Any or Universal (U)]
Main Application	Industrial Service
Atmosphere	Gas
Rated Avg. Life @ 120v	3500 hr
Estimated Energy Cost/YR	7.23 \$
Life with 3h/day use [years]	1.6 an

• Light Technical Characteristics

Color Temperature	2590 K
Initial lumen	540 Lm
Initial Lumens @ 120V	395 Lm

• Electrical Characteristics

Watts	60 W
-------	------

Voltage	130 V
---------	-------

• Product Dimensions

Light Center Length L	2.992 in
Max Overall Length (MOL) - C	4.438 (max) in
Diameter D	2.375 in

• Footnotes


Footnotes Incandescent	902 [Exclusive to Philips Lighting Company.]
------------------------	--

• Product Data

Product number	222489
Full product name	Ind Ser 60W Med 130V A19 FR 2WR
Short product name	Ind Ser 60W Med 130V A19 FR 2WR
Pieces per Sku	1
eop_pck_cfg	48
Skus/Case	48
Bar code on pack	46677222482
Bar code on case	50046677222487
Logistics code(s)	925280736110
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

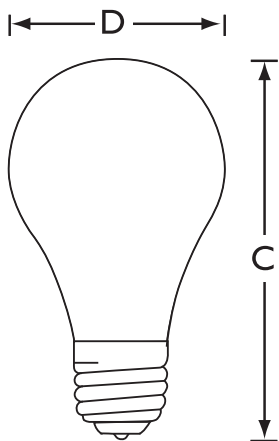

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 60W E26 130V A19 FR	4.438	2.375



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change