



Econ-O-Watt

Econ-O-Watt 67W 130V A19 FR EW 2WR

Philips Econ-o-watt® Standard Lamps can directly replace standard life incandescent lamps, offering instant energy savings for many applications.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Frosted
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Econ-o-watt
Atmosphere	Gas
Rated Avg. Life @ 120v	2120 hr

• Light Technical Characteristics

Initial lumen	990 Lm
Initial Lumens @ 120V	805 Lm

• Electrical Characteristics

Watts	67 W
Voltage	130 V

• Product Dimensions

Light Center Length L	2.953 in
-----------------------	----------

Max Overall Length (MOL) - C	4.438 (max) in
Diameter D	2.375 in

• Footnotes


Footnotes Incandescent	905 [Consider the compact fluorescent lamps for energy savings.]
------------------------	--

• Product Data

Product number	222414
Full product name	Econ-O-Watt 67W 130V A19 FR EW 2WR
Short product name	Econ 67W 130V A19 FR EW 2WR
Pieces per Sku	1
eop_pck_cfg	48
Skus/Case	48
Bar code on pack	46677222413
Bar code on case	50046677222418
Logistics code(s)	925281536102
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

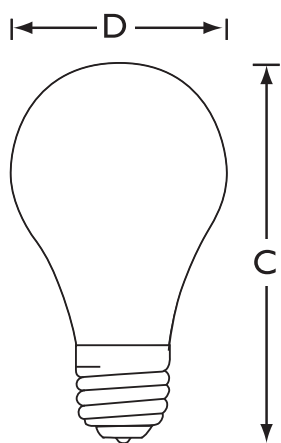

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 67W E26 130V A19 FR	4.438	2.375



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change