



# DuraMax Clear

DuraMax 100W Med 120V A19 CLLL TP 2OW

Philips DuraMax® Long Life Light Bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. A wide assortment of shapes, sizes and wattages ensure that there is a DuraMax product to meet most basic lighting needs.

## Product data

### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Finish	Clear
Filament Shape	CC6 [Straight]
Operating Position	Universal [Any or Universal (U)]
Main Application	Household
Atmosphere	Gas

### • Light Technical Characteristics

Initial lumen	1470 Lm
---------------	---------

### • Electrical Characteristics

Watts	100 W
Voltage	120 V

### • Product Dimensions

Light Center Length L	2.953 in
--------------------------	----------


Max Overall Length (MOL) - C	4.438 (max) in
Diameter D	2.375 in

### • Product Data

Product number	150086
Full product name	DuraMax 100W Med 120V A19 CLLL TP 2OW
Short product name	DuraMax 100W Med 120V A19 CLLL TP 2OW
Pieces per Sku	2
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677167950
Bar code on case	50046677150087
Logistics code(s)	925283836314
eop_net_weight_pp	0.000 kg

## Dimensional drawing

Dimensional drawing

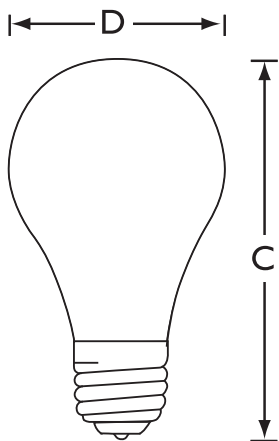

A19



E26

E26, A19

Product	C (Max)	D (Norm)
Std 100W E26 120V A19 CL	4.438	2.375



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change