



Frost / Clear

150W Med 120V A21 FR 1WR

The Philips Family of Standard Frost and Clear bulbs are good for everyday use. Clear bulbs provide sparkle, especially in fixtures that are made of chrome, have mirrored surfaces, multiple sockets or have cut glass parts. If glare is a problem, use a dimmer or a lower wattage bulb to reduce brightness. Clear bulbs are also used in fixtures with reflectors. Frost bulbs provide soft light with reduced glare.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Bulb	A21
Bulb Finish	Frosted
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Gas
Rated Avg. Life @ 120v	2140 hr
Estimated Energy Cost/YR	18.07 \$
Life with 3h/day use [years]	0.7 an

• Light Technical Characteristics

Color Temperature	2840 K
Initial lumen	2620 Lm
Initial Lumens @ 120V	2174 Lm

• Electrical Characteristics

Watts	150 W
-------	-------

Voltage	120 V
---------	-------

• Product Dimensions

Max Overall Length (MOL) - C	5.312 (max) in
Diameter D	2.625 in

• Footnotes


Footnotes Incandescent	905 [Consider the compact fluorescent lamps for energy savings.]
------------------------	--

• Product Data

Product number	270033
Full product name	150W Med 120V A21 FR 1WR
Short product name	150W Med 120V A21 FR 1WR
Pieces per Sku	1
eop_pck_cfg	48
Skus/Case	48
Bar code on pack	46677270032
Bar code on case	50046677270037
Logistics code(s)	925287336306
eop_net_weight_pp	0.001 kg

Dimensional drawing

Dimensional drawing

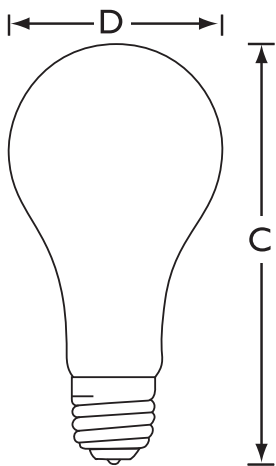

A21



E26

E26, A21

Product	C (Max)	D (Norm)
150W E26 120V A21 FR	5.312	2.625



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change