



## Frost / Clear

150W Med 120-130V A23 FR 2WR

The Philips Family of Standard Frost and Clear bulbs are good for everyday use. Clear bulbs provide sparkle, especially in fixtures that are made of chrome, have mirrored surfaces, multiple sockets or have cut glass parts. If glare is a problem, use a dimmer or a lower wattage bulb to reduce brightness. Clear bulbs are also used in fixtures with reflectors. Frost bulbs provide soft light with reduced glare.

### Product data

#### • General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A23
Bulb Finish	Frosted
Filament Shape	CC-8 [Axial]
Atmosphere	Gas
RatedAvgLife(See Family Notes)	750 hr

#### • Light Technical Characteristics

Initial lumen	2700 Lm
---------------	---------

#### • Electrical Characteristics

Watts	150 W
-------	-------

Voltage	120-130 V
---------	-----------

#### • Product Dimensions


Max Overall Length (MOL) - C	6.313 (max) in
Diameter D	2.875 in

#### • Product Data

Product number	281725
Full product name	150W Med 120-130V A23 FR 2WR
Short product name	150W Med 120-130V A23 FR 2WR
Pieces per Sku	1
Skus/Case	60
Bar code on pack	046677281724
Bar code on case	50046677281729
Logistics code(s)	925288034304

### Dimensional drawing

Dimensional drawing

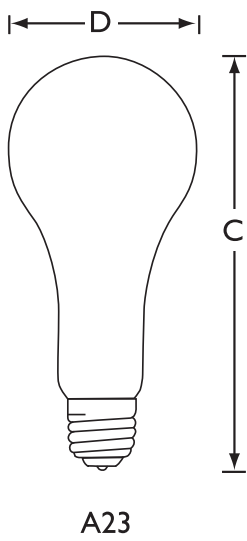

A23



E26

E26, A23

Product	C (Max)	D (Norm)
150W E26 120-130V A23 FR	6.313	2.875



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change