

DuraMax Deco Blunt Tip

DuraMax Deco 25W Cand 120V B-10 1/2 CL 2BC



Philips DuraMax® Long Life Decorative blunt tip bulbs reduce the hassle of replacing light bulbs every few months, since all DuraMax products last longer than standard incandescent light bulbs. Philips Duramax decorative blunt tip bulbs are available in a variety of shapes, sizes and wattages with clear and frost finishes. The clear bulbs provide decorative sparkle, while the frost bulbs add a soft glow to add a pleasant touch to home decor.

Product data

• General Characteristics

Base	Candelabra [Candelabra Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	B-10 1/2
Bulb Finish	Clear
Filament Shape	C-7A [Ring]
Operating Position	Base Down +/- 90D [Standing +/-90D or Base Down (BDH)]
Main Application	Decorative
Atmosphere	Gas

• Light Technical Characteristics

Initial lumen	150 Lm
---------------	--------

• Electrical Characteristics

Watts	25 W
Voltage	120 V


• Product Dimensions

Max Overall Length (MOL) - C	4.063 (max) in
Diameter D	1.313 in


• Product Data

Product number	168245
Full product name	DuraMax Deco 25W Cand 120V B-10 1/2 CL 2BC
Short product name	DMax Deco 25W Cand 120V B-10 1/2 CL 2BC
Pieces per Sku	2
eop_pck_cfg	6
Skus/Case	6
Bar code on pack	46677168247
Bar code on case	50046677168242
Logistics code(s)	925288336308
eop_net_weight_pp	0.000 kg


Dimensional drawing

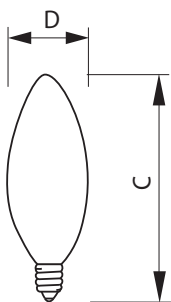

E12, B10 1/2

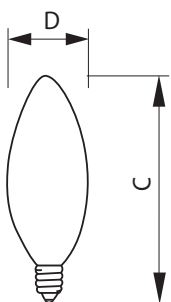

E12, B10 1/2

 

E12



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change