



EcoVantage

72W 120V A19 D-BEV 2CT

The new EcoVantage bulbs reduce energy consumption without sacrificing the qualities of a traditional bulb. They uniquely produce light more efficiently. They work with dimmer switches and are available in the familiar A-shape design. Use them in existing fixtures just as you would standard incandescents and your home will look great while you save energy.

Product data

• General Characteristics

Base	Medium [Single Contact Medium Screw]
Base Information	Aluminum [Aluminum Base]
Bulb	A19
Bulb Material	Soft Glass
Bulb Finish	Daylight-Blue
Filament Shape	CC-8 [Axial]
Operating Position	Universal [Any or Universal (U)]
Main Application	General Lighting
Atmosphere	Gas
Rated Avg. Life @ 120v	1250 hr

• Light Technical Characteristics

Color Rendering Index	100 Ra8
Initial lumen	1200 Lm

• Electrical Characteristics


Watts	72 W
Voltage	120 V

• Product Data

Product number	226993
Full product name	72W 120V A19 D-BEV 2CT
Short product name	72W 120V A19 D-BEV 2CT
Pieces per Sku	2
eop_pck_cfg	12
Skus/Case	12
Bar code on pack	46677226992
Bar code on case	50046677226997
Logistics code(s)	925620820601
eop_net_weight_pp	0.000 kg

Dimensional drawing

Dimensional drawing

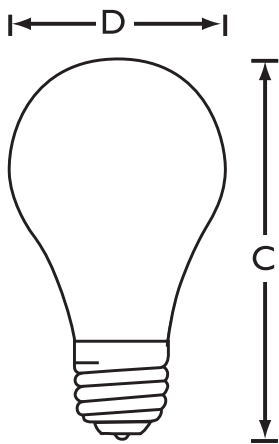

A19



E26

E26, A19

Product	C (Max)	D (Norm)
72W E26/ALC 120V A-19 D-B	-	-



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change