

Circline

FC6T9 Cool White Plus

T9 4-Pin Circular Fluorescent Lamps.

Product data

• General Characteristics

| | |
|------------------------------|--------------------------------|
| Base | G10q |
| Base Information | Plastic |
| Bulb | T3 [Diameter: 9 mm /.354 inch] |
| Rated Avg. Life [3 hr Start] | 12000 hr |

• Light Technical Characteristics

| | |
|-----------------------|------------|
| Color Code | 33 |
| Color Rendering Index | 62 Ra8 |
| Color Designation | Cool White |
| Color Temperature | 4100 K |
| Initial lumen | 800 Lm |
| Design Mean Lumens | 590 Lm |

• Electrical Characteristics

| | |
|-------|------|
| Watts | 20 W |
|-------|------|

• Product Dimensions

| | |
|-----------------------|-----|
| Nominal Length [inch] | 6.5 |
|-----------------------|-----|


• Product Data

| | |
|--------------------|----------------------------|
| Product number | 249821 |
| Full product name | FC6T9 Cool White Plus |
| Short product name | FC6T9/COOL WHITE PLUS 12PK |
| Pieces per Sku | 1 |
| Skus/Case | 12 |
| Bar code on pack | 46677249823 |
| Bar code on case | 50046677249828 |
| Logistics code(s) | 927828203302 |
| eop_net_weight_pp | 0.001 kg |


PHILIPS

sense and simplicity


Dimensional drawing

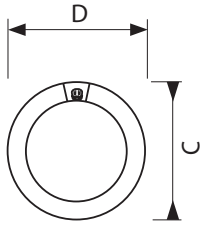

G10q, T9

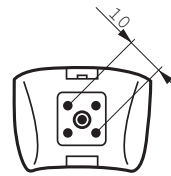

G10q

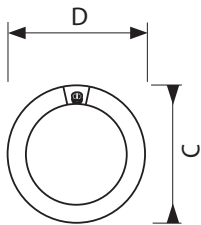

G10q, T9



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change