



U-Bent Rapid Start T8

FB32T8/6 TL841 ALTO

Philips leads the industry with the lowest level mercury technology. Reducing the mercury level (source reduction) during the manufacturing phase is essential to creating products that are less harmful to the environment.

Product data

• General Characteristics

Base	Medium Bi-Pin [Medium Bi-Pin Fluorescent]
Base Information	Green Base
Bulb	T8-6U [U-bent T 8/8 inch with 6" spacing]
Rated Avg. Life [3 hr Start]	20000 hr
Rated Avg Life [12 Hr Start]	24000 hr
Energy Saving	Energy Saving

• Light Technical Characteristics

Color Code	TL841 [CCT of 4100K]
Color Rendering Index	85 Ra8
Color Designation	TL841
Color Temperature	4100 K
Initial lumen	2800 Lm
Design Mean Lumens	2535 Lm

• Electrical Characteristics

Watts	32 W
-------	------

• Environmental Characteristics

Mercury (Hg) Content	3.0 mg
Picogram per Lumen Hour	59 p/LuHr

• Product Dimensions

Nominal Length [inch]	22.44
-----------------------	-------

• Product Data

Product number	379024
Full product name	FB32T8/6 TL841 ALTO
Short product name	FB32T8/6 TL841 ALTO/20
Pieces per Sku	1
eop_pck_cfg	20
Skus/Case	20
Bar code on pack	46677379025
Bar code on case	50046677379020
Logistics code(s)	927860084102
eop_net_weight_pp	0.001 kg

PHILIPS

 
sense and simplicity

U-Bent Rapid Start T8


Dimensional drawing



G13, T8-U



G13

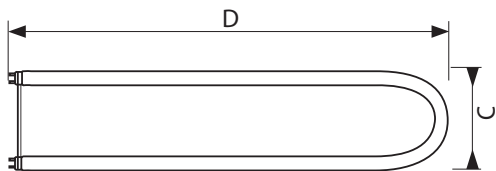

G13, T8-U



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change