



U-Bent Energy Advantage T8

FB32T8/6 25W ADV841 XEW ALTO

Philips Energy Advantage T8 25W U-Bent Lamps are environmentally responsible lamps, featuring energy savings and low mercury.

Product data

• General Characteristics

Base	Medium Bi-Pin [Medium Bi-Pin Fluorescent]
Base Information	Green Base
Bulb	T8-6U [U-bent T 8/8 inch with 6" spacing]
Rated Avg. Life [3 hr Start]	20000 hr
Energy Saving	Energy Saving

• Light Technical Characteristics

Color Code	Advantage 841 [CCT of 4100K]
Color Rendering Index	85 Ra8
Color Designation	Advantage 841
Color Temperature	4100 K
Initial lumen	2400 Lm
Design Mean Lumens	2330 Lm

• Electrical Characteristics

Watts	25 W
-------	------

• Environmental Characteristics

Mercury (Hg) Content	3.0 mg
Picogram per Lumen Hour	64 p/LuHr

• Product Dimensions

Nominal Length [inch]	22.44
-----------------------	-------

 
• Product Data

Product number	204230
Full product name	FB32T8/6 25W ADV841 XEW ALTO
Short product name	FB32T8/6 25W ADV841 XEW ALTO
Pieces per Sku	1
eop_pck_cfg	20
Skus/Case	20
Bar code on pack	46677204235
Bar code on case	50046677204230
Logistics code(s)	927860184201
eop_net_weight_pp	0.001 kg


Dimensional drawing



G13, T8-UEA



G13

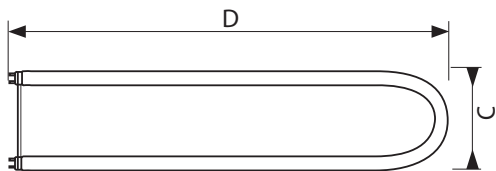

G13, T8-UEA



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change