



# U-Bent Energy Advantage T8

FB32T8/6 25W ADV850 XEW ALTO

Philips Energy Advantage T8 25W U-Bent Lamps are environmentally responsible lamps, featuring energy savings and low mercury.

## Product data

### • General Characteristics

Base	Medium Bi-Pin [Medium Bi-Pin Fluorescent]
Base Information	Green Base
Bulb	T8-6U [U-bent T 8/8 inch with 6" spacing]
Rated Avg. Life [3 hr Start]	20000 hr
Energy Saving	Energy Saving

### • Light Technical Characteristics

Color Code	Advantage 850 [CCT of 5000K]
Color Rendering Index	85 Ra8
Color Designation	Advantage 850
Color Temperature	5000 K
Initial lumen	2350 Lm
Design Mean Lumens	2280 Lm

### • Electrical Characteristics

Watts	25 W
-------	------

### • Environmental Characteristics

Mercury (Hg) Content	3.0 mg
Picogram per Lumen Hour	66 p/LuHr

### • Product Dimensions

Nominal Length [inch]	22.44
-----------------------	-------

 
### • Product Data

Product number	204248
Full product name	FB32T8/6 25W ADV850 XEW ALTO
Short product name	FB32T8/6 25W ADV850 XEW ALTO
Pieces per Sku	1
eop_pck_cfg	20
Skus/Case	20
Bar code on pack	46677204242
Bar code on case	50046677204247
Logistics code(s)	927860185101
eop_net_weight_pp	0.001 kg


## Dimensional drawing



G13, T8-UEA



G13

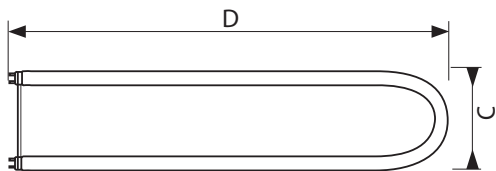

G13, T8-UEA



© 2012 Koninklijke Philips Electronics N.V.  
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

[www.philips.com/lighting](http://www.philips.com/lighting)

2012, August 4  
data subject to change