



U-Bent Rapid Start T8

FB31T8 TL830 ALTO 1SL

Philips leads the industry with the lowest level mercury technology. Reducing the mercury level (source reduction) during the manufacturing phase is essential to creating products that are less harmful to the environment.

Product data

• General Characteristics

Base	Medium Bi-Pin [Medium Bi-Pin Fluorescent]
Base Information	Green Base
Bulb	T8-1-5/8U [U-bent T 1inch with 1-5/8" leg spacing]
Rated Avg. Life [3 hr Start]	24000 hr
Rated Avg Life [12 Hr Start]	30000 hr
Energy Saving	Energy Saving

• Light Technical Characteristics

Color Code	TL830 [CCT of 3000K]
Color Rendering Index	85 Ra8
Color Designation	TL830
Color Temperature	3000 K
Initial lumen	2750 Lm
Design Mean Lumens	2430 Lm

• Electrical Characteristics

Watts	31 W
-------	------

• Environmental Characteristics

Mercury (Hg) Content	3.0 mg
----------------------	--------

• Product Dimensions

Nominal Length [inch]	22.44
-----------------------	-------

• Product Data

Product number	226712
Full product name	FB31T8 TL830 ALTO 1SL
Short product name	FB31T8 TL830 ALTO 1SL
Pieces per Sku	1
eop_pck_cfg	15
Skus/Case	15
Bar code on pack	46677226718
Bar code on case	50046677226713
Logistics code(s)	927861283002
eop_net_weight_pp	0.001 kg

PHILIPS

 
sense and simplicity

U-Bent Rapid Start T8


Dimensional drawing



G13, T8-U



G13

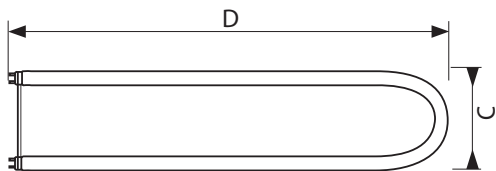

G13, T8-U



© 2012 Koninklijke Philips Electronics N.V.
All rights reserved.

Specifications are subject to change without notice. Trademarks are the property of Koninklijke Philips Electronics N.V. or their respective owners.

www.philips.com/lighting

2012, August 4
data subject to change